

H6,0/23T ZH GN


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

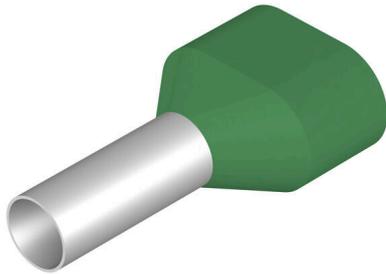

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, green
Order No.	9037690000
Type	H6,0/23T ZH GN
GTIN (EAN)	4008 190493486
Qty.	100 items
Packaging	loose

H6,0/23T ZH GN

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.53 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, green	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	4.5 mm	Contact surface length (L2)	12 mm
Collar width (B)	6.2 mm	Collar height (A)	11.4 mm
Plastic collar thickness (S2)	0.5 mm	L1 in mm	23.00 mm
Wire connection cross section AWG, max.	AWG 10	Metal sleeve thickness (S1)	0.2 mm
Stripping length	20 mm	Conductor cross-section	6 mm ²
Colour code	Telemecanique		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

