

## LIS 6M8 V


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

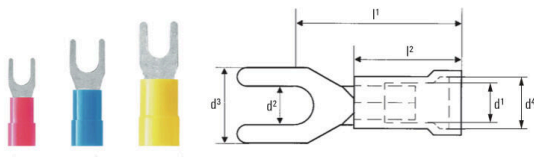

Insulated forked-cable connector made from PVC or PC/  
PA

- Conventional designs
- Not soldered
- With conical entry funnel

### General ordering data

Version	cable lug, terminal end, Insulated cable connector, 4 mm <sup>2</sup> - 6 mm <sup>2</sup> , yellow
Order No.	<a href="#">9200440000</a>
Type	LIS 6M8 V
GTIN (EAN)	40322484 10286
Qty.	50 items

## LIS 6M8 V

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	8 mm	Depth (inches)	0.315 inch
Width	33.2 mm	Width (inches)	1.3071 inch
Net weight	1.24 g		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Technical data

Description of article	Insulated forked-cable connector 6.0 mm <sup>2</sup> / M8
------------------------	---

### Connectors

Conductor cross-section, max.	6 mm <sup>2</sup>	Conductor cross-section, min.	4 mm <sup>2</sup>
Insulation	Available	Dimension (bolt)	M 8
Dimension	M 8	Material/plastic	PVC
Identification colour	yellow	Connection density (S1)	1 mm
Inside diameter (d1)	8.4 mm	Plastic collar length (b)	13.15 mm
Plastic collar diameter (D)	6.4 mm	Outside diameter (d)	14 mm

### Classifications

ETIM 8.0	EC001059	ETIM 9.0	EC001059
ETIM 10.0	EC001059	ECLASS 14.0	27-40-02-92
ECLASS 15.0	27-40-02-92		

Drawings

