


LIP 1,5R12 V**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

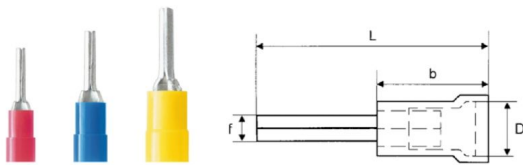

Insulated pin-cable connector made from PVC or PC/PA

- Conventional designs
- Not soldered
- With conical entry funnel

General ordering data

Version	cable lug, terminal end, Insulated cable connector, 0.5 mm ² - 1.5 mm ² , red
Order No.	9200460000
Type	LIP 1,5R12 V
GTIN (EAN)	4032248410309
Qty.	100 items

LIP 1,5R12 V

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	5.8 mm	Depth (inches)	0.2283 inch
Width	23.3 mm	Width (inches)	0.9173 inch
Net weight	0.71 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Insulated pin-cable connector 1.5 mm ² L=12 mm
------------------------	---

Connectors

Conductor cross-section, max.	1.5 mm ²	Conductor cross-section, min.	0.5 mm ²
Insulation	Available, PVC	Dimension (pin length)	12 mm
Dimension	12.0 mm	Material/plastic	PVC
Length 1 (l1)	22 mm	Identification colour	red
Outside diameter of shaft (d3)	1.9 mm	Plastic collar length (b)	10 mm
Plastic collar diameter (D)	4.3 mm		

Classifications

ETIM 8.0	EC001059	ETIM 9.0	EC001059
ETIM 10.0	EC001059	ECLASS 14.0	27-40-02-92
ECLASS 15.0	27-40-02-92		

Drawings

