


## LIB 2,5B25 VF

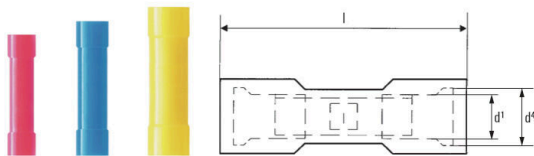

Fully-insulated joint connector made from PVC or PC/PA

- Conventional designs
- Not soldered

### General ordering data

Version	cable lug, terminal end, Insulated cable connector, 1.5 mm <sup>2</sup> - 2.5 mm <sup>2</sup> , blue
Order No.	<a href="#">9200500000</a>
Type	LIB 2,5B25 VF
GTIN (EAN)	4032248410347
Qty.	100 items

## LIB 2,5B25 VF

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	6.2 mm	Depth (inches)	0.2441 inch
Width	26 mm	Width (inches)	1.0236 inch
Net weight	1.38 g		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Technical data

Description of article	Insulated joint connector 2.5 mm <sup>2</sup> L=24.5 mm
------------------------	--

### Connectors

Conductor cross-section, max.	2.5 mm <sup>2</sup>	Conductor cross-section, min.	1.5 mm <sup>2</sup>
Insulation	Available	Dimension (pin length)	24.5 mm
Dimension	24.5 mm	Material/plastic	PVC
Identification colour	blue	Plastic collar diameter (D)	4.3 mm

### Classifications

ETIM 8.0	EC001059	ETIM 9.0	EC001059
ETIM 10.0	EC001059	ECLASS 14.0	27-40-02-12
ECLASS 15.0	27-40-02-12		

Drawings

