


H0,75/19TS ZH HBL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

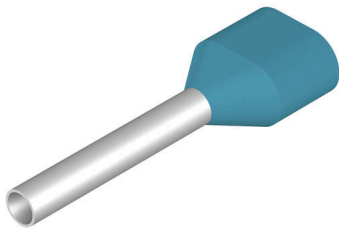

- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
Material: E-Cu, tin galvanised
Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, Light Blue
Order No.	9202840000
Type	H0,75/19TS ZH HBL
GTIN (EAN)	4032248515783
Qty.	500 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986

Dimensions and weights

Net weight	0.16 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, light blue	Version	Twin wire-end ferrule
------------------------	-----------------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	12 mm
Collar width (B)	3 mm	Collar height (A)	5.5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	19.00 mm
Wire connection cross section AWG, max.	AWG 18	Metal sleeve thickness (S1)	0.15 mm
Stripping length	15 mm	Conductor cross-section	0.75 mm ²
Colour code	Miscellaneous		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

