


## H0,75/19TS ZH HBL

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

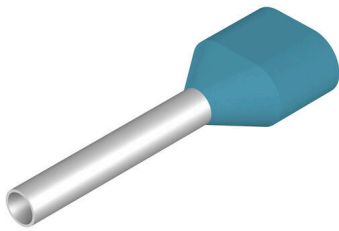

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

### General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, Light Blue
Order No.	<a href="#">9202840000</a>
Type	H0,75/19TS ZH HBL
GTIN (EAN)	4032248515783
Qty.	500 items
Packaging	loose

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E354986

**Dimensions and weights**

Net weight	0.16 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Twin wire end ferrule, light blue	Version	Twin wire-end ferrule
------------------------	-----------------------------------	---------	-----------------------

**Wire-end ferrules**

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	12 mm
Collar width (B)	3 mm	Collar height (A)	5.5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	19.00 mm
Wire connection cross section AWG, max.	AWG 18	Metal sleeve thickness (S1)	0.15 mm
Stripping length	15 mm	Conductor cross-section	0.75 mm <sup>2</sup>
Colour code	Miscellaneous		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

