


SAIL-VSB-0.3U**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

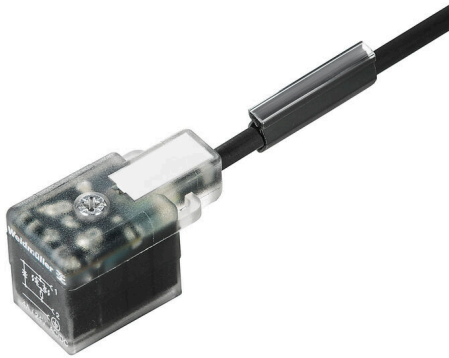

Weidmüller can supply valve plugs as connecting lines with M8/M12 plugs and one end without connector. The status of the valve plug is shown by an LED. The valve plugs have a protective circuit. The Weidmüller range includes valve plugs of type A, B and C to DIN and industry standards. Protection class IP 67 is fulfilled when screwed in. The outlet direction is also a decisive factor, therefore Weidmüller offers different versions.

General ordering data

Version	Sensor-actuator Cable, Number of poles: 3, 0.5 m, LED: No, Shielded:
Order No.	9457930030
Type	SAIL-VSB-0.3U
GTIN (EAN)	4064675041818
Qty.	1 items
Delivery status	This article will no longer be available in the future.
Last order date	2027-02-28T00:00:00+01:00

Technical data

Approvals

Approvals	CE; UKCA
ROHS	Conform

Dimensions and weights

Net weight	30 g
------------	------

Technical specifications for cable

Cable length	0.5 m	Sheathing colour	black
Acceleration	5 m/s ²	Bending radius, min., moving	10 x cable diameter
Bending radius, min., stationary	5 x cable diameter	Bending cycles	2 Mio
Speed	200 m/s	Sheath material	PUR
Irradiation crosslinked	No	Colour coding	brown, blue, Green/yellow
Number of poles	3	Outside diameter	4.6 mm ± 0.2 mm

General technical data

LED	No
-----	----

Classifications


ETIM 8.0	EC001855	ETIM 9.0	EC001855
ETIM 10.0	EC001855	ECLASS 14.0	27-06-03-11
ECLASS 15.0	27-06-03-11		

Drawings

Dimensioned drawing



Pole scheme

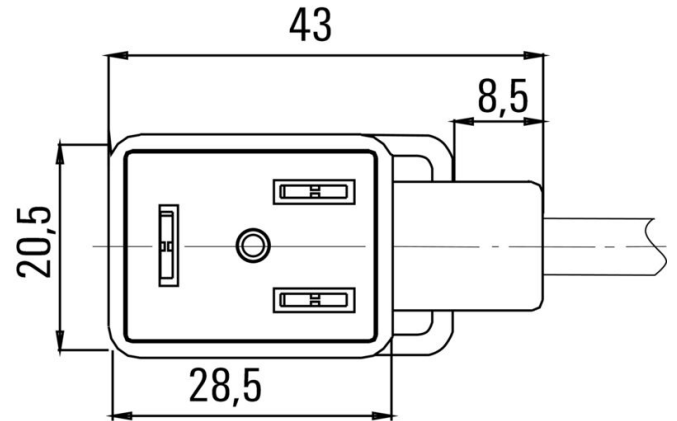

Wiring diagram

