

## HDC MPN 6.0 F

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmuller.com



Make your connections fit for the future With the advanced solutions from RockStar® ModuPlug Industrial applications are becoming increasingly complex. The demands being made of the connectivity used are growing at the same time. Functionality in the smallest of installation spaces, safe installation and a fast retrofitting process are just some of the product properties being called for. Not only does our RockStar® ModuPlug modular plug-in connector system meet current market requirements; it has been specially designed with the future in mind too. Using the individual modules, you combine all the necessary functions for power, signal and data transmission in a single interface. Thanks to the new variety of module sizes, you can fit more applications than ever before in one plug-in connector. The modules reduce the amount of space required and cut costs when compared with fixed-pole inserts and other modular plug-in connector systems. The sophisticated frames and modules can be installed with extreme ease and integrated into HDC enclosures with the IP65 and IP68 protection classes. You can even use the RockStar® ModuPlug to supplement existing applications without any need to make system adjustments. As an experienced Industrial Connectivity partner, Weidmüller offers ultra-modern connectivity with maximum reliability. So you can create customised solutions for future-proof connections with RockStar® too.

## Általános rendelési adatok

|                |   |
|----------------|---|
| Változat       | Pneumatikus csatlakozók, Érintkezés a szeleppel:<br>Nem |
| Rendelési szám | <a href="#">2637390000</a>                              |
| Típus          | HDC MPN 6.0 F   |
| GTIN (EAN)     | 4050118654530   |
| Qty.           | 10 Darab  |

## HDC MPN 6.0 F

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Műszaki adatok

### Tanúsítványok

|      |          |
|------|----------|
| ROHS | Megfelel |
|------|----------|

### Méreték és tömegek

|             |        |
|-------------|--------|
| Nettó tömeg | 1.07 g |
|-------------|--------|

### Hőmérsékletek

|                         |                  |
|-------------------------|------------------|
| Hőmérsékleti határérték | -40 °C ... 80 °C |
|-------------------------|------------------|

### Termékek környezetvédelmi megfelelősége

|                            |                               |
|----------------------------|-------------------------------|
| RoHS megfelelőségi állapot | Megfelel, kivétel nélkül      |
| REACH SVHC                 | Nincs 0,1 tömeg% feletti SVHC |

### Pneumatikus csatlakozó

|                       |        |                        |        |
|-----------------------|--------|------------------------|--------|
| Típus                 | Hüvely | Üzemi nyomás           | ≤8 bar |
| Tömítő belső átmérője | 6 mm   | Érintkezés a szeleppel | Nem    |

### Besorolások

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC002943    | ETIM 9.0    | EC002943    |
| ETIM 10.0   | EC002943    | ECLASS 14.0 | 27-44-02-92 |
| ECLASS 15.0 | 27-44-02-92 |             |             |


## HDC MPN 6.0 F

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Tartozékok

www.weidmueller.com

## Pneumatikus modulok

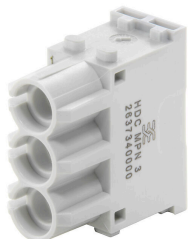

## Flexible

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

## Általános rendelési adatok

|                |                            |  |
|----------------|----------------------------|--|
| Típus          | HDC MPN 2                  | Változat   |
| Rendelési szám | <a href="#">2637320000</a> | Pneumatikus modul, Pólusszám: 2, Csőcsatlakozás (pneumatika), pneumatikus, Dugaszhelyek szükséges száma: 1 |
| GTIN (EAN)     | 4050118767520              |  |
| Qty.           | 1 ST                       |  |