


KOBBS 19X75**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

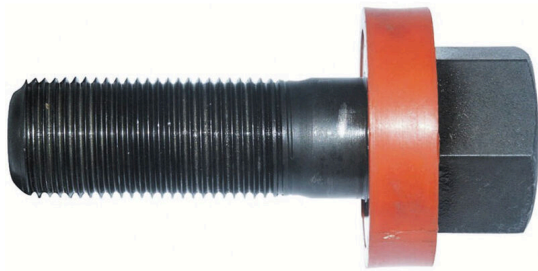

- Overpressure valve protects against overloading
- Cylinder head angled at 90°
- Angled head can be rotated through 360°
- Ergonomic handle springs back automatically
- The waste piece no longer becomes jammed thanks to triple splitting
- Hydraulic punch made of high-strength aluminium (approx. 40% weight saving)
- Service life greatly reduced when stainless steel sheets are used

Not suitable for stainless steel!

Általános rendelési adatok

Változat	Sheet holes
Rendelési szám	9204780000
Típus	KOBBS 19X75
GTIN (EAN)	4032248693146
Qty.	1 Darab

KOBBS 19X75**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germanywww.weidmueller.com**Műszaki adatok****Méreték és tömegek**

Magasság	75 mm	Magasság (coll)	2.9527 inch
Átmérő	19 mm	Nettó tömeg	255.2 g

Termékek környezetvédelmi megfelelése

RoHS megfelelési állapot	Nem érintett
REACH SVHC	Lead 7439-92-1
SCIP	6a3438d7-aa8c-48e4-8879-adf736ca79e3

Műszaki adatok

Árucikk leírása	Feszítőcsavar csapágyakkal, 19,0 x 75,0 mm
-----------------	--

Besorolások

ETIM 8.0	EC000149	ETIM 9.0	EC000149
ETIM 10.0	EC000149	ECLASS 14.0	21-04-50-03
ECLASS 15.0	21-04-50-03		