


KOBBS 9.5X50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

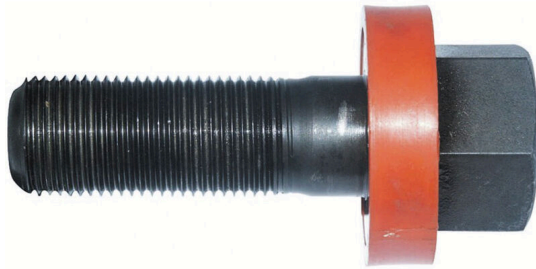

- Overpressure valve protects against overloading
- Cylinder head angled at 90°
- Angled head can be rotated through 360°
- Ergonomic handle springs back automatically
- The waste piece no longer becomes jammed thanks to triple splitting
- Hydraulic punch made of high-strength aluminium (approx. 40% weight saving)
- Service life greatly reduced when stainless steel sheets are used

Not suitable for stainless steel!

Általános rendelési adatok

Változat	Sheet holes
Rendelési szám	9205030000
Típus	KOBBS 9.5X50
GTIN (EAN)	4032248694266
Qty.	1 Darab

KOBBS 9.5X50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Méreték és tömegek

Magasság	50 mm	Magasság (coll)	1.9685 inch
Átmérő	9.5 mm	Nettó tömeg	63 g

Termékek környezetvédelmi megfelelése

RoHS megfelelési állapot	Nem érintett
REACH SVHC	Lead 7439-92-1
SCIP	6a3438d7-aa8c-48e4-8879-adf736ca79e3

Műszaki adatok

Árucikk leírása	Feszítőcsavar csapágyakkal, 9,5 x 50,0 mm
-----------------	---

Besorolások

ETIM 8.0	EC000149	ETIM 9.0	EC000149
ETIM 10.0	EC000149	ECLASS 14.0	21-04-50-03
ECLASS 15.0	21-04-50-03		