


KOBBS 19X55**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

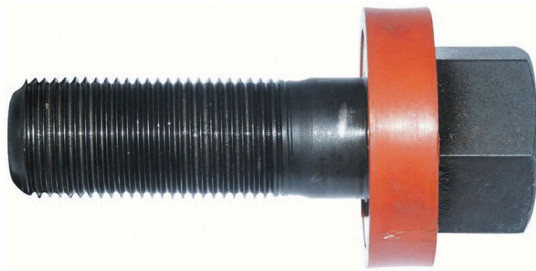

- Overpressure valve protects against overloading
- Cylinder head angled at 90°
- Angled head can be rotated through 360°
- Ergonomic handle springs back automatically
- The waste piece no longer becomes jammed thanks to triple splitting
- Hydraulic punch made of high-strength aluminium (approx. 40% weight saving)
- Service life greatly reduced when stainless steel sheets are used

Not suitable for stainless steel!

Általános rendelési adatok

| | |
|----------------|----------------------------|
| Változat | Sheet holes |
| Rendelési szám | 9205040000 |
| Típus | KOBBS 19X55 |
| GTIN (EAN) | 4032248694273 |
| Qty. | 1 Darab |

KOBBS 19X55

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Méretek és tömegek

| | | | |
|----------|-------|-----------------|-------------|
| Magasság | 55 mm | Magasság (coll) | 2.1654 inch |
| Átmérő | 19 mm | Nettó tömeg | 245 g |

Termékek környezetvédelmi megfelelése

| | |
|--------------------------|--------------------------------------|
| RoHS megfelelési állapot | Nem érintett |
| REACH SVHC | Lead 7439-92-1 |
| SCIP | 6a3438d7-aa8c-48e4-8879-adf736ca79e3 |

Műszaki adatok

| | |
|-----------------|--|
| Árucikk leírása | Feszítőcsavar csapágyakkal, 19,0 x 55,0 mm |
|-----------------|--|

Besorolások

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000149 | ETIM 9.0 | EC000149 |
| ETIM 10.0 | EC000149 | ECLASS 14.0 | 21-04-50-03 |
| ECLASS 15.0 | 21-04-50-03 | | |