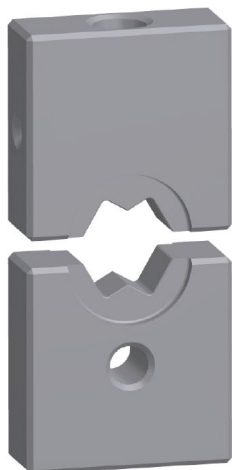


ES APG 80 WM10**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

Dati generali per l'ordinazione

Versione	10mm ² , Crimpatura a WM
N. d'ordine	1502440000
Tipo	ES APG 80 WM10
GTIN (EAN)	4050118310542
CPZ	1 Pieza

ES APG 80 WM10

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Dati tecnici

Dimensioni e pesi

Peso netto	337.7 g
------------	---------

Conformità ambientale del prodotto

Stato conformità RoHS	Conforme senza esenzione
REACH SVHC	No SVHC above 0.1 wt%

Dati utensile di crimpatura

Tipo/profilo di crimpatura	Crimpatura a WM
Sezione capicorda	nominale 10 mm ²

Descrizione contatto

Sezione del conduttore max. AWG	8	Sezione del conduttore min. AWG	8
Area di crimpatura , max.	10 mm ²		

Inseriti a crimpare

Larghezza di crimpatura	7 mm	Sezione trasversale a crimpare in rame	10
Larghezza di crimpatura in mm	7		

Classificazioni

ETIM 6.0	EC001282	ETIM 7.0	EC001282
ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 9.0	21-04-90-90
ECLASS 9.1	21-01-90-90	ECLASS 10.0	21-04-90-90
ECLASS 11.0	21-04-90-90	ECLASS 12.0	21-04-90-90
ECLASS 13.0	21-04-90-90	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

ES APG 80 WM10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessori

Utensili



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

Dati generali per l'ordinazione

Tipo	APG 80	Versione
N. d'ordine	1502390000	6mm ² , 400mm ²
GTIN (EAN)	4050118310627	
CPZ	1 ST	

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

Dati generali per l'ordinazione

Tipo	KRN-M4/-10	Versione
N. d'ordine	1496900000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306293	
CPZ	100 ST	
Tipo	KRN-M5/-10	Versione
N. d'ordine	1496910000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306378	
CPZ	100 ST	
Tipo	KRN-M6/-10	Versione
N. d'ordine	1496920000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306439	
CPZ	100 ST	
Tipo	KRN-M8/-10	Versione
N. d'ordine	1496930000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306552	
CPZ	100 ST	
Tipo	KRN-M10/-10	Versione
N. d'ordine	1496940000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306521	
CPZ	100 ST	

ES APG 80 WM10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessori

Tipo	KRN-M12/-10	Versione
N. d'ordine	1496950000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306453	
CPZ	100 ST	
Tipo	KWN-M5/-10 90	Versione
N. d'ordine	1497020000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306712	
CPZ	100 ST	
Tipo	KWN-M6/-10 90	Versione
N. d'ordine	1497030000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306484	
CPZ	100 ST	
Tipo	KWN-M8/-10 90	Versione
N. d'ordine	1497040000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306576	
CPZ	100 ST	
Tipo	KWN-M10/-10 90	Versione
N. d'ordine	1497050000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306750	
CPZ	100 ST	
Tipo	KWN-M12/-10 90	Versione
N. d'ordine	1497070000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306606	
CPZ	100 ST	
Tipo	KWN-M5/-10 45	Versione
N. d'ordine	1496810000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306309	
CPZ	100 ST	
Tipo	KWN-M6/-10 45	Versione
N. d'ordine	1496820000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306286	
CPZ	100 ST	
Tipo	KWN-M8/-10 45	Versione
N. d'ordine	1496830000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306330	
CPZ	100 ST	
Tipo	KWN-M10/-10 45	Versione
N. d'ordine	1496840000	Spine piatte, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306361	
CPZ	100 ST	
Tipo	VSTN/-10	Versione
N. d'ordine	1497130000	Spine piatte, 10 mm ² , 10 mm ² , Nessuno
GTIN (EAN)	4050118306491	
CPZ	50 ST	
Tipo	KP-M5/-10	Versione
N. d'ordine	1497870000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118307252	
CPZ	100 ST	
Tipo	KP-M6/-10	Versione
N. d'ordine	1497880000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118307283	
CPZ	100 ST	

ES APG 80 WM10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessori

Tipo	KP-M8/-10	Versione
N. d'ordine	1497890000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118307573	
CPZ	100 ST	
Tipo	KP-M10/-10	Versione
N. d'ordine	1497910000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118307276	
CPZ	100 ST	
Tipo	KWPN-M6/-10 90	Versione
N. d'ordine	1497420000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118307023	
CPZ	100 ST	
Tipo	KWPN-M8/-10 90	Versione
N. d'ordine	1497430000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118306927	
CPZ	100 ST	
Tipo	VPN/-10	Versione
N. d'ordine	1498620000	Spine piatte, 10 mm ² , 10 mm ² , Nessuno
GTIN (EAN)	4050118308136	
CPZ	100 ST	
Tipo	KQN-M4/-10	Versione
N. d'ordine	1494010000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118303810	
CPZ	100 ST	
Tipo	KQN-M5/-10	Versione
N. d'ordine	1494020000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118303681	
CPZ	100 ST	
Tipo	KQN-M6/-10	Versione
N. d'ordine	1494030000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118303483	
CPZ	100 ST	
Tipo	KQN-M8/-10	Versione
N. d'ordine	1494040000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118303803	
CPZ	100 ST	
Tipo	KQN-M10/-10	Versione
N. d'ordine	1494050000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118303711	
CPZ	100 ST	
Tipo	KQN-M12/-10	Versione
N. d'ordine	1494060000	Spine piatte, 10 mm ²
GTIN (EAN)	4050118304008	
CPZ	100 ST	
Tipo	KQNG-M5/-10	Versione
N. d'ordine	1492680000	Spine piatte, 10 mm ² , 10 mm ²
GTIN (EAN)	4050118302479	
CPZ	100 ST	
Tipo	KQNG-M6/-10	Versione
N. d'ordine	1492690000	Spine piatte, 10 mm ² , 10 mm ²
GTIN (EAN)	4050118302394	
CPZ	100 ST	

ES APG 80 WM10**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessori**

Tipo	KSN/-10	Versione
N. d'ordine	1492780000	Spine piatte, 10 mm ² , 10 mm ²
GTIN (EAN)	4050118302806	
CPZ	100 ST	
Tipo	VPLN/-10	Versione
N. d'ordine	1492890000	Spine piatte, 10 mm ² , 10 mm ² , Nessuno
GTIN (EAN)	4050118302561	
CPZ	100 ST	
Tipo	VSTN/10	Versione
N. d'ordine	1493030000	Spine piatte, 10 mm ² , 10 mm ² , Nessuno
GTIN (EAN)	4050118302776	
CPZ	100 ST	