

D-SERIES DRI의 소켓용 점프바

일반 주문 데이터

버전	D-SERIES, 점프바
주문 번호	7760056366
유형	SCM/SDI P CC
GTIN (EAN)	6944169773327
수량	10 items

기술 데이터

승인

ROHS 준수

치수 및 중량

깊이	18.2 mm	깊이 (인치)	0.7165 inch
높이	5.7 mm	높이 (인치)	0.2244 inch
너비	12.1 mm	폭 (인치)	0.4764 inch
순중량	1 g		

온도

보관 온도 작동 온도

환경 제품 규정 준수

RoHS 준수 상태 준수, 예외 미존재
 REACH SVHC 0.1 wt% 이상의 SVHC 없음

점프바 데이터

정격 전압	250 V	정격 전류	2 A
절연	Yes	접촉 보호	예
컬러 코드	주황색	교차 연결된 단자대 개수	2
극 수	2	피치(mm)(P)	8.00 mm
장착 유형	플러그	버전	D-시리즈 소켓용 (PUSH IN 결선 포함)

일반 데이터

버전 D-시리즈 소켓용 (PUSH IN
결선 포함) 컬러 코드 주황색

절연 조정

정격 전압 250 V

결선 데이터

피치(mm)(P) 8.00 mm

분류

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		


SCM/SDI P CC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

도면


Dimensional drawing

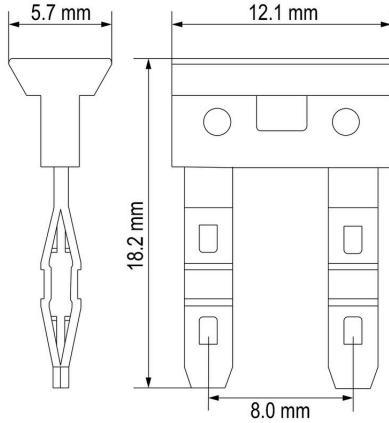

사용 예

How to install cross connection

to cross connect A2 contacts of SDI... PUSH IN sockets

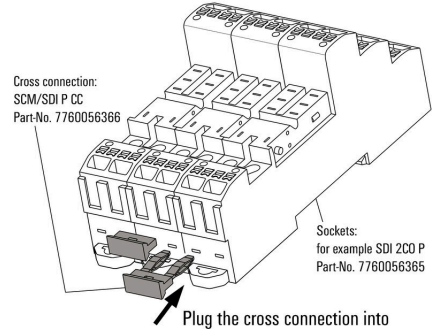

Cross connection:
SCM/SDI P CC
Part-No. 7760056366

Sockets:
for example SDI 2CO P
Part-No. 7760056365


Plug the cross connection into
the provided connection points

점프바 설치 방법:SDI의 A2
접점 교차 결선... PUSH IN 소켓

사용 예

How to install cross connection

to cross connect A2 contacts of SCM... PUSH IN sockets

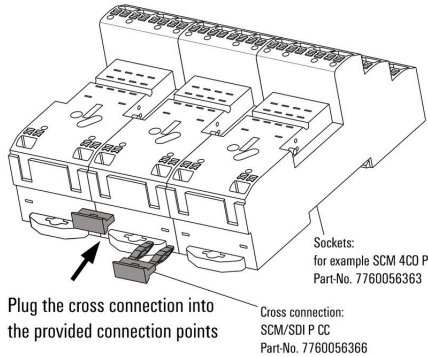

Plug the cross connection into
the provided connection points

Cross connection:
SCM/SDI P CC
Part-No. 7760056366

Sockets:
for example SCM 4CO P
Part-No. 7760056363

점프바 설치 방법:SCM의 A2
접점 교차 결선... PUSH IN 소켓

사용 예

Cross connection

between SDI... and SCM... PUSH IN sockets is possible

