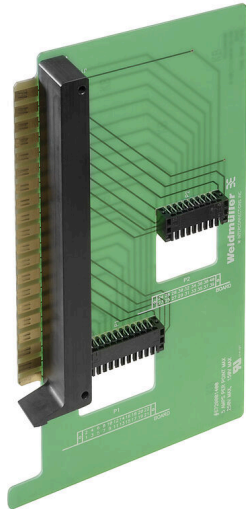


SP-RS PLC PLC5 1771-WN 40CH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

**Genomföringsanslutning**

- PLC-5 1771 ombyggnad till jackbar(a) anslutning(ar)
- Kort med 10, 12, 18, 21 eller 40 punkter

Allmänna beställningsdata

Art.nr.	6720001400
Typ	SP-RS PLC PLC5 1771-WN 40CH
GTIN (EAN)	4050118765878
Förp.	1 items

SP-RS PLC PLC5 1771-WN 40CH

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Tekniska data

Godkännanden

ROHS	Uppfyllelse
------	-------------

Mått och vikter

Djup	142 mm	Byggdjup (tum)	5.5905 inch
Höjd	254 mm	Bygghöjd (tum)	10 inch
Bredd	30 mm	Byggbredd (tum)	1.1811 inch
Nettovikt	196 g		

Temperaturer

Lagertemperatur	0...50 °C	Drifttemperatur	5...50 °C
-----------------	-----------	-----------------	-----------

Miljööverensstämmelse för produkt

RoHS-kompatibilitetsstatus	Kompatibel utan undantag
REACH SVHC	Nej mSvHC över 0,1 viktprocent

Märkdata UL

Märkström I _{max} .	10 A
------------------------------	------

Klassificeringar

ETIM 8.0	EC002584	ETIM 9.0	EC002584
ETIM 10.0	EC002584	ECLASS 14.0	27-33-02-92
ECLASS 15.0	27-33-02-92		

SP-RS PLC PLC5 1771-WN 40CH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Ritningar

www.weidmueller.com



The image shows a small, vertically oriented technical drawing or table of data. It contains a grid of small text and symbols, likely representing a pinout or connection table for the PLC5 1771-WN 40CH. The text is too small to read clearly, but it appears to be organized in columns and rows.